

Part No: 442-025F

Fabricated Fittings

Elbow

Desc: 2-1/2 PVC 22-1/2 ST ELL SPIGOTXSOC SCH40

MSRP: 61.33

Part Code: 047

Weight(lbs): 0.617


Weight(kg): 0.28

Weight(gm): 280

Size: 2-1/2"

Color: WHITE

Material: PVC

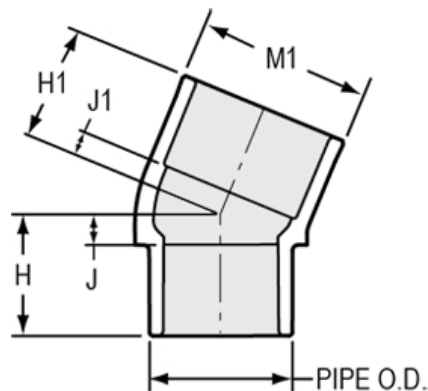

Schedule SCH 40

Angle 22-1/2 Degree

Connection Spigot X Socket

Type Standard

H = 4-11/16

H1 = 1-11/16

J = 1-15/16

J1 = 5/16

M1 = 3- 1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

