

Part No: 442-120F

Fabricated Fittings

Elbow

Desc: 12 PVC 22-1/2ST ELL SPGXSOC SCH40

MSRP: 497.81

Part Code: 047

Weight(lbs): 15.763


Weight(kg): 7.15

Weight(gm): 7150

Size: 12"

Color: WHITE

Material: PVC

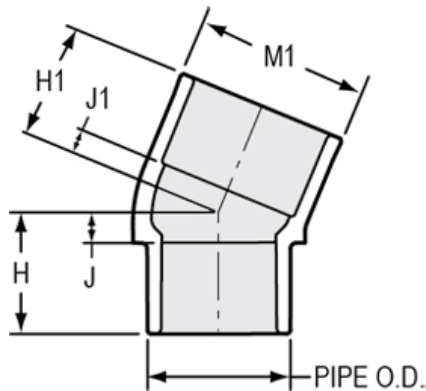

Schedule SCH 40

Angle 22-1/2 Degree

Connection Spigot X Socket

Type Standard

H = 12-1/4

H1 = 5-3/16

J = 5-1/4

J1 = 1-1/16

M1 = 13-9/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

