

Part No: 4423CB-012

Valves

Industrial Swing Check Valve

Desc: 1-1/4 PVC SWNG CHK FLNGD COUNTR/BAL EPDM

MSRP: 1285.42

Part Code: 108

Weight(lbs): 9.683

Weight(kg): 4.392

Weight(gm): 4392

Size: 1-1/4"

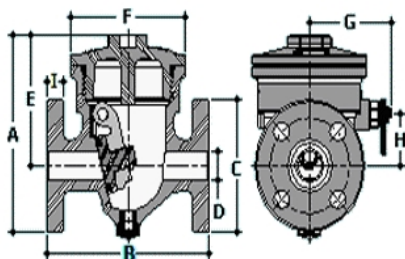
Color: BEIGE

Material: PVC

Type W/Counter Balance

O-Ring EPDM

Pressure Rating 150 PSI @ 73° F


No of
Bolts = 4

Bolt = 3- 1/2
Circle
Dia.

Bolt Size = 5/8

I = 23/32

Cv = 70
Values

D = 1-19/32

E = 4- 9/16

F = 5- 3/4

G = 4- 3/8

H = 1-27/32

A = 7- 3/8

B = 7- 3/32

C = 5

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

