

Part No: 4433I-007P

Valves

Industrial Swing Check Valve

Desc: 3/4 PP SWING CHECK VALVE FLNGD FKM W/IND

MSRP: 1064.64

Part Code: 113

Weight(lbs): 1.299

Weight(kg): 0.589

Weight(gm): 589

Size: 3/4"


Color: BEIGE

Material: Polypropylene

Type W/Indicator

O-Ring FKM

Pressure Rating 150 PSI @ 73° F

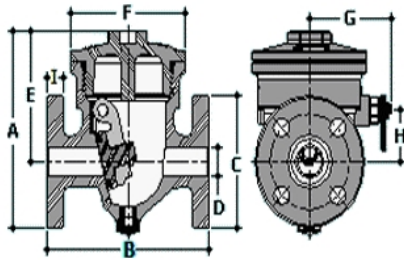

A = 5- 5/16

B = 5- 1/2

C = 3- 7/8

D = 3/4

E = 3- 3/4

F = 3- 3/4

Cv = 18
Values

No of = 4
Bolts

Bolt = 2- 3/4
Circle
Dia.

Bolt Size = 5/8

G = 3

H = 1- 7/16

I = 1/2

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

