

Part No: 446-003

Schedule 40 White

Adapter

Desc: 3/8 PVC IPT ADAPTER MPTXFPT SCH40

MSRP: 3.32

Part Code: 040

Weight(lbs): 0.022

Weight(kg): 0.01


Weight(gm): 10

Size: 3/8"

Color: WHITE

Material: PVC

Connection Mipt x Fipt
Type Standard

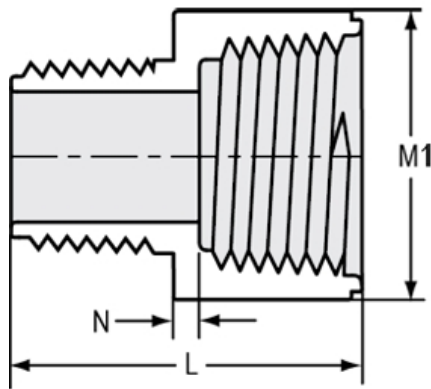

L = 1-13/32

M1 = 1

N = 5/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

