

**Part No:** 447-020B

**Schedule 40 Black**

**Cap/Plug**

**Desc:** 2 PVC CAP SOC SCH40 BLK

**MSRP:** 3.52

**Part Code:** 011

**Weight(lbs):** 0.165

**Weight(kg):** 0.075

**Weight(gm):** 75


**Size:** 2"

**Color:** BLACK

**Material:** PVC Black

**Connection** Socket

**Type** Cap

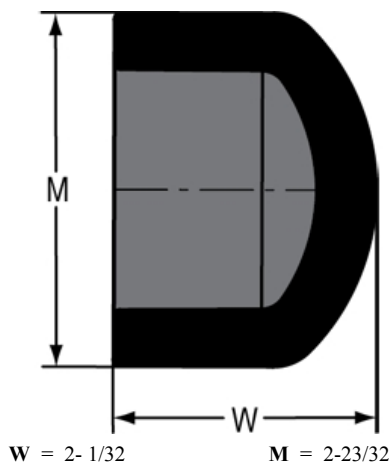

$W = 2 - 1/32$

$M = 2 - 23/32$

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

