

Part No: 4527-007

Valves

Ball Check Valve

Desc: 3/4 PVC TU2K IND BALL CHECK SPIGOT EPDM

MSRP: 112.87

Part Code: 604

Weight(lbs): 0.507

Weight(kg): 0.23

Weight(gm): 230

Size: 3/4"


Color: GRAY

Material: PVC

Connection Spigot (TU 2000)

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

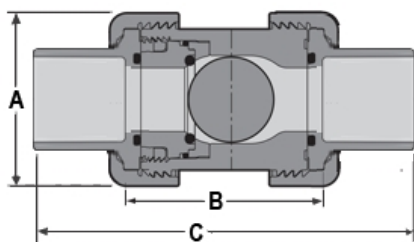

A = 2- 1/4

B = 3- 1/4

C = 5- 1/4

Cv = 17
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

