

Part No: 4529-005BL

Low Extractable

Valves

Desc: 1/2 PVC LE TU2KINDBCV SOC/FPT EPDM

MSRP: 229.98

Part Code: 066

Weight(lbs): 0.346


Weight(kg): 0.157

Weight(gm): 157

Size: 1/2"

Color: BLUE

Material: PVC LE

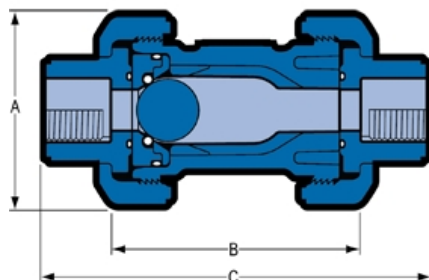

Type TU 2000 Ball Check Valve
Connection Fipt + Socket
O-Ring EPDM
Pressure Rating 235 psi @ 73° F

A = 1-15/16

B = 2- 7/16

C = 4- 3/16

Cv = 6.3
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

