

Part No: 4529-007BL

Low Extractable

Valves

Desc: 3/4 PVC LE TU2K INDBCVC SOC/FPT EPDM

MSRP: 277.81

Part Code: 066

Weight(lbs): 0.529

Weight(kg): 0.24

Weight(gm): 240

Size: 3/4"

Color: BLUE


Material: PVC LE

Type TU 2000 Ball Check Valve

Connection Fipt + Socket

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

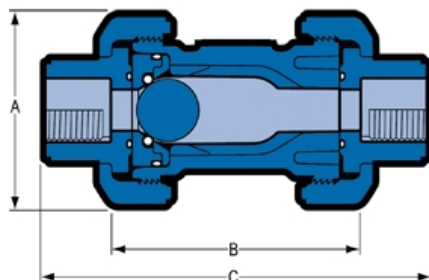

A = 2-3/8

B = 2- 3/4

C = 4- 3/4

Cv = 17
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

