

Part No: 4529-015BL

Low Extractable

Valves

Desc: 1-1/2 PVC LE TU2K INDBALCV SOC/FPT EPDM

MSRP: 595.88

Part Code: 066

Weight(lbs): 1.656


Weight(kg): 0.751

Weight(gm): 751

Size: 1-1/2"

Color: BLUE

Material: PVC LE

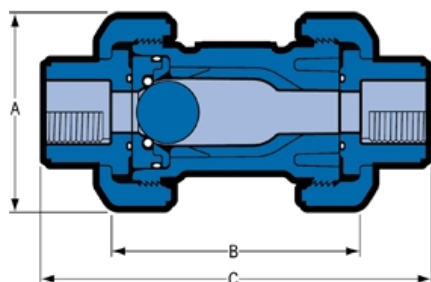

Type TU 2000 Ball Check Valve

Connection Fipt + Socket

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

A = 3-9/16

B = 3-9/16

C = 6-5/16

Cv = 86
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

