

Part No: 4529-020BL

Low Extractable

Valves

Desc: 2 PVC LE TU2K INDBALCHKVLV SOC/FPT EPDM

MSRP: 996.32

Part Code: 066

Weight(lbs): 2.824

Weight(kg): 1.281

Weight(gm): 1281

Size: 2"

Color: BLUE


Material: PVC LE

Type TU 2000 Ball Check Valve

Connection Fipt + Socket

O-Ring EPDM

Pressure Rating 235 psi @ 73° F

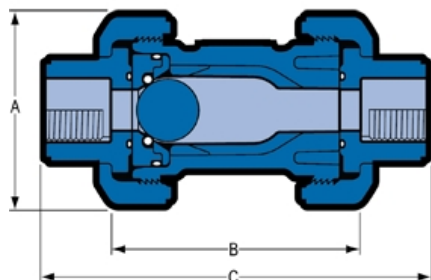

A = 4-5/16

B = 4-13/16

C = 7-13/16

Cv = 130
Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

