

Part No: 4533-012

Valves

Ball Check Valve

Desc: 1-1/4 PVC TU2K IND BALL CHECK FLG FKM

MSRP: 305.88

Part Code: 604

Weight(lbs): 2.046

Weight(kg): 0.928

Weight(gm): 928

Size: 1-1/4"


Color: GRAY

Material: PVC

Connection Flanged (TU 2000)

O-Ring FKM

Pressure Rating 150 psi @ 73° F

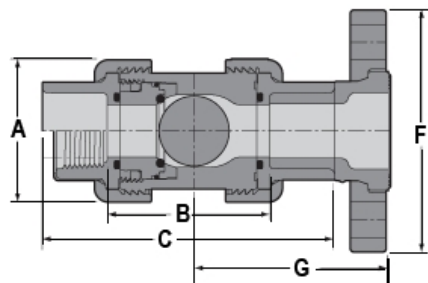

A = 3- 1/16

B = 3- 1/4

C = 5- 3/4

F = 4- 5/8

G = 3-31/32

Cv = 65

Values

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

