

Part No: 457-010G

Schedule 40 Gray

Union

Desc: 1 PVC UNION SOCXSOC BUNA SCH40 GRAY

MSRP: 13.77

Part Code: 043

Weight(lbs): 0.179

Weight(kg): 0.081

Weight(gm): 81


Size: 1"

Color: GRAY

Material: PVC

Connection Socket x Socket

O-Ring Buna - N

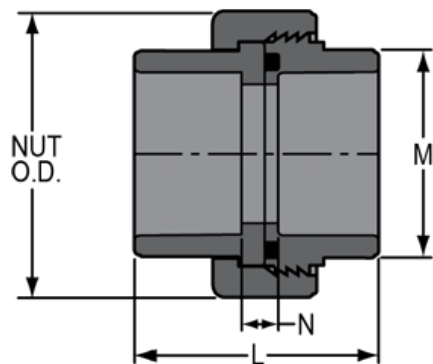

L = 2- 7/16

M = 1- 5/8

N = 11/32

NUT = 2- 3/8
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

