

Part No: 457-012G

Schedule 40 Gray

Union

Desc: 1-1/4 PVC UNION SOCXSOC BUNA SCH40 GRAY

MSRP: 44.42

Part Code: 043

Weight(lbs): 0.247

Weight(kg): 0.112

Weight(gm): 112


Size: 1-1/4"

Color: GRAY

Material: PVC

Connection Socket x Socket

O-Ring Buna - N

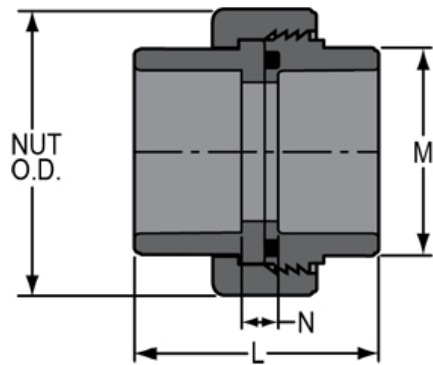

L = 2-29/32

M = 1-31/32

N = 13/32

NUT = 2-11/16
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

