

Part No: 457-015G

Schedule 40 Gray

Union

Desc: 1-1/2 PVC UNION SOCXSOC BUNA SCH40 GRAY

MSRP: 46.31

Part Code: 043

Weight(lbs): 0.324

Weight(kg): 0.147

Weight(gm): 147


Size: 1-1/2"

Color: GRAY

Material: PVC

Connection Socket x Socket

O-Ring Buna - N

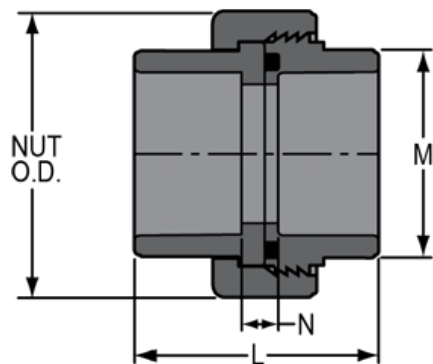

L = 3- 1/32

M = 2- 1/4

N = 3/8

NUT = 3- 3/32
O.D.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

