

Part No: 460-040G

Inserts

Adapter

Desc: 4 PVC GRAY ADAPTER INSERTXSPIGOT SCH40

MSRP: 39.91

Part Code: 043

Weight(lbs): 0.73

Weight(kg): 0.331

Weight(gm): 331


Size: 4

Color: GRAY

Material: PVC

Connection Insert x IPS Spigot

Type Standard

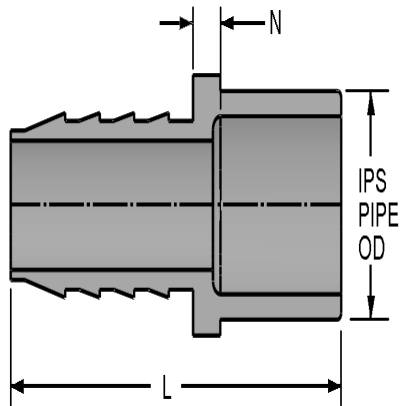

L = 5-3/8

N = 5/16

Z = 4-1/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

