

Part No: 467E-415SR

Schedule 40 White

Clamp-On Saddle

Desc: 4X1/2 PVC CLMP SADDLE SRFPT EPDM ZNC BLT

MSRP: 100.1

Part Code: 046

Weight(lbs): 1.343


Weight(kg): 0.609

Weight(gm): 609

Size: 4"X1/2"

Color: WHITE

Material: PVC

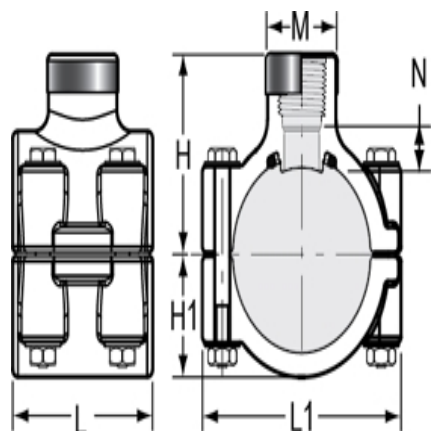

H = 4-1/32

H1 = 2-5/8

L = 3

L1 = 5-13/16

M = 1-23/32

N = 1-1/16

No of Bolts = 4

Min Hole Size = 1-1/8

Bolt Torque = 8
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

