

Part No: 467S-250SR

Schedule 40 White

Clamp-On Saddle

Desc: 2X1-1/4 PVC CLAMP SDL SRFPT BUNA SS BOLT

MSRP: 87.26

Part Code: 046

Weight(lbs): 0.679


Weight(kg): 0.308

Weight(gm): 308

Size: 2"X1-1/4"

Color: WHITE

Material: PVC

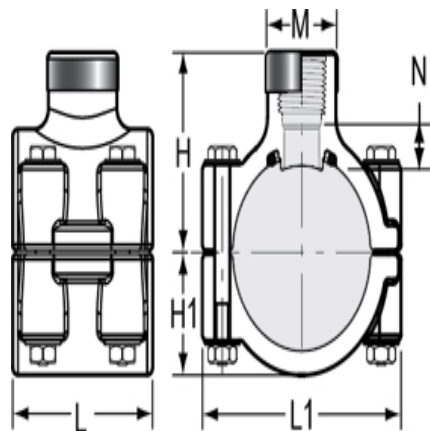

H = 2-13/16

H1 = 1-1/2

L = 2-7/16

L1 = 3-7/16

M = 2-1/16

N = 11/16

Bolt = 8

Min Hole = 1-1/2

No of = 4

Torque
FT./LBS.

Hardware SS

Connection Single SR Fipt (Clamp-On)

O-Ring Buna-N

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

