

Part No: 467S-335SR

Schedule 40 White

Clamp-On Saddle

Desc: 3X1 PVC CLAMP SADDLE SRFPT BUNA SS BOLT

MSRP: 117.33

Part Code: 046

Weight(lbs): 0.911


Weight(kg): 0.413

Weight(gm): 413

Size: 3"X1"

Color: WHITE

Material: PVC

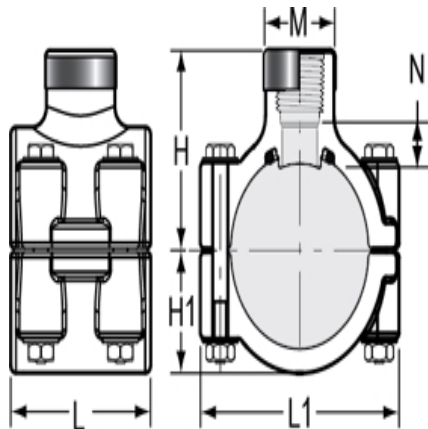

H = 3- 3/16

H1 = 2

L = 3

L1 = 4-3/4

M = 1-23/32

N = 17/32

No of Bolts = 4

Min Hole Size = 1-1/8

Bolt Torque = 8
FT./LBS.

Connection Single SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

