

Part No: 467S-337SR

Schedule 40 White

Clamp-On Saddle

Desc: 3X1-1/2 PVC CLMP SADDLE SRFPT BUNA SSBLT

MSRP: 117.33

Part Code: 046

Weight(lbs): 1.442


Weight(kg): 0.654

Weight(gm): 654

Size: 3"X1-1/2"

Color: WHITE

Material: PVC

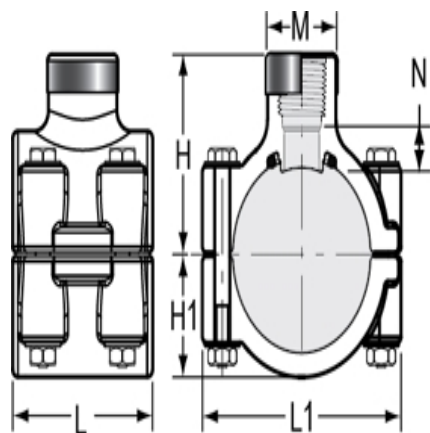

H = 3-7/8

No of Bolts = 4

Min Hole Size = 2-1/4

Bolt Torque = 8
FT./LBS.

H1 = 2

L = 4-1/8

L1 = 4-3/4

M = 3-1/32

N = 1-3/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

