

**Part No:** 467S-422SR

**Schedule 40 White**

**Clamp-On Saddle**

**Desc:** 4X3 PVC CLAMP SADDLE SRFPT BUNA SS BOLT

**MSRP:** 165.82

**Part Code:** 046

**Weight(lbs):** 2.637


**Weight(kg):** 1.196

**Weight(gm):** 1196

**Size:** 4"X3"

**Color:** WHITE

**Material:** PVC

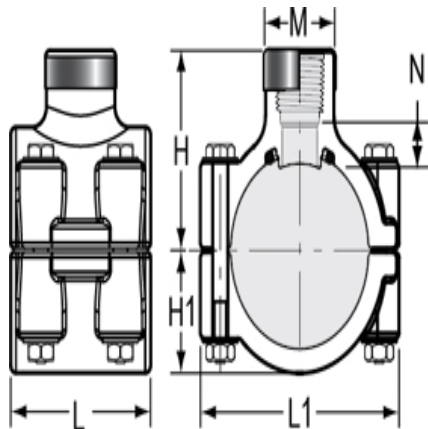

**H** = 4-3/4

**H1** = 2-5/8

**L** = 5-1/2

**L1** = 5-13/16

**M** = 4-5/16

**N** = 1

**No of Bolts** = 4

**Min Hole Size** = 3

**Bolt Torque** = 8  
FT./LBS.

**Connection** Single SR Fipt (Clamp-On)

**O-Ring** Buna-N

**Hardware** SS

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

