

Part No: 467S-579SR

Schedule 40 White

Clamp-On Saddle

Desc: 8X2-1/2 PVC CLMP SDDLE SRFPT BUNA SS BLT

MSRP: 384.82

Part Code: 046

Weight(lbs): 9.555


Weight(kg): 4.334

Weight(gm): 4334

Size: 8"X2-1/2"

Color: WHITE

Material: PVC

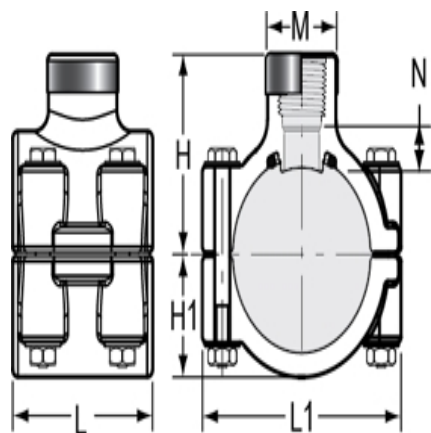

H = 7-11/16

H1 = 4-7/8

L = 8- 1/2

L1 = 10-1/16

M = 5- 1/4

N = 1-3/4

No of Bolts = 6

Min Hole Size = 4

Bolt Torque = 10
FT./LBS.

Connection Single SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

