

Part No: 467S-585SR

Schedule 40 White

Clamp-On Saddle

Desc: 8X6 PVC CLAMP SADDLE BUNA SRFPT SS BOLT

MSRP: 470.89

Part Code: 046

Weight(lbs): 10.3


Weight(kg): 4.672

Weight(gm): 4672

Size: 8"X6"

Color: WHITE

Material: PVC

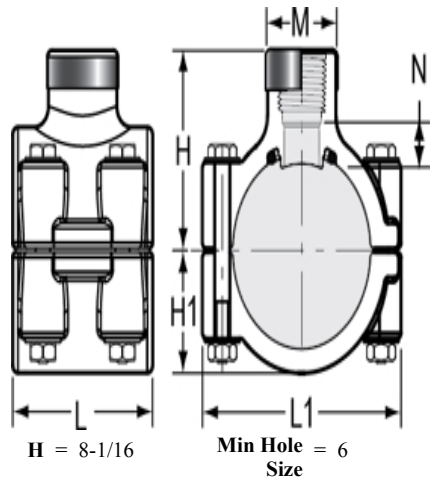

Connection Single SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

H = 8-1/16

Min Hole Size = 6

Bolt Torque = 10
FT./LBS.

H1 = 4-7/8

L = 8-1/2

L1 = 10-1/16

M = 7-21/32

N = 2-1/4

No of Bolts = 6

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

