

Part No: 468-527

Schedule 40 White

Clamp-On Saddle

Desc: 6X1-1/2 PVC CLAMP SADDLE D/O SOC BUNA ZN

MSRP: 160.63

Part Code: 046

Weight(lbs): 3.732

Weight(kg): 1.693

Weight(gm): 1693

Size: 6"X1-1/2"


Color: WHITE

Material: PVC

Connection Double Socket (Clamp-On)

O-Ring Buna-N

Hardware Zinc

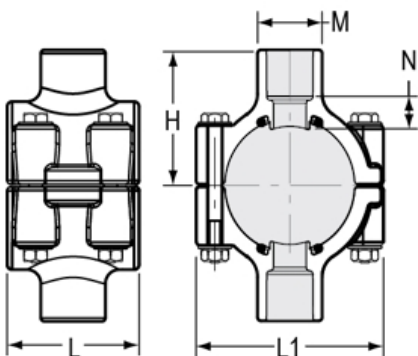

H = 5-11/16

L = 4- 1/8

L1 = 8-3/16

M = 3

N = 1-1/16

**No of
Bolts** = 4

**Min Hole
Size** = 2-1/4

**Bolt = 10
Torque
FT./LBS.**

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

