

Part No: 468E-336

Schedule 40 White

Clamp-On Saddle

Desc: 3X1-1/4 PVC CLAMP SADDLE D/O SOC EPDM ZN

MSRP: 83.74

Part Code: 046

Weight(lbs): 1.885

Weight(kg): 0.855

Weight(gm): 855

Size: 3"X1-1/4"


Color: WHITE

Material: PVC

Connection Double Socket (Clamp-On)

O-Ring EPDM

Hardware Zinc

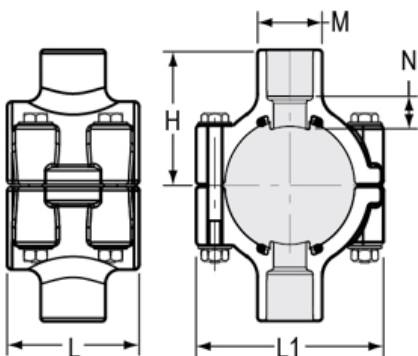

H = 3-7/8

L = 4-1/8

L1 = 4-3/4

M = 3

N = 7/8

No of Bolts = 4

Min Hole Size = 2-1/4

Bolt Torque = 8
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

