

Part No: 468E-574

Schedule 40 White

Clamp-On Saddle

Desc: 8X3/4 PVC CLAMP SADDLE D/O SOC EPDM ZN B

MSRP: 257.96

Part Code: 046

Weight(lbs): 8.878

Weight(kg): 4.027

Weight(gm): 4027

Size: 8"X3/4"


Color: WHITE

Material: PVC

Connection Double Socket (Clamp-On)

O-Ring EPDM

Hardware Zinc

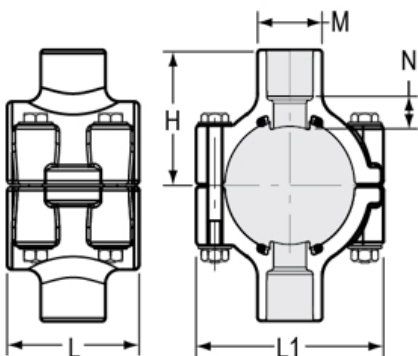

No of Bolts = 6

Min Hole Size = 2-1/8

Bolt Torque = 10
FT./LBS.

H = 6-11/16

L = 8- 1/2

L1 = 10-1/16

M = 3

N = 1-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

