

Part No: 468SE-248

Schedule 40 White

Clamp-On Saddle

Desc: 2X3/4 PVC CLAMP SADDLE D/O SOC EPDM SSBT

MSRP: 98.98

Part Code: 046

Weight(lbs): 0.694

Weight(kg): 0.315

Weight(gm): 315

Size: 2"X3/4"


Color: WHITE

Material: PVC

Connection Double Socket (Clamp-On)

O-Ring EPDM

Hardware SS

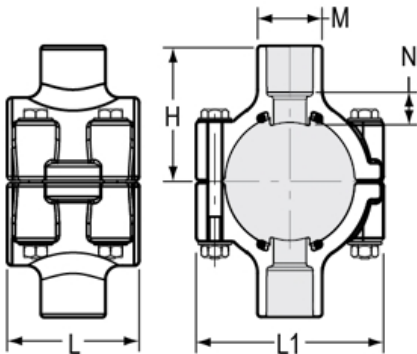

H = 2-9/16

L = 2- 7/16

L1 = 3- 7/16

M = 1- 3/8

N = 5/16

No of Bolts = 4

Min Hole Size = 7/8

Bolt Torque = 8
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

