

**Part No:** 468SE-526

**Schedule** 40 White

**Clamp-On Saddle**

**Desc:** 6X1-1/4 PVC CLAMP SADDLL D/O SOC EPDM SS

**MSRP:** 272.32

**Part Code:** 046

**Weight(lbs):** 3.702

**Weight(kg):** 1.679

**Weight(gm):** 1679

**Size:** 6"X1-1/4"


**Color:** WHITE

**Material:** PVC

**Connection** Double Socket (Clamp-On)

**O-Ring** EPDM

**Hardware** SS

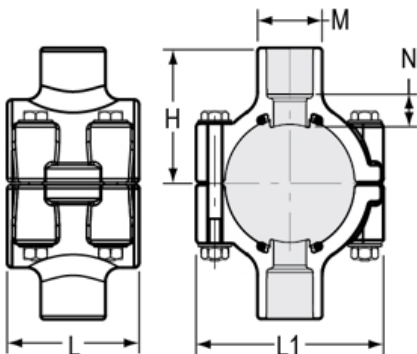

**H** = 5-11/16

**L** = 4- 1/8

**L1** = 8-3/16

**M** = 3

**N** = 1-1/8

**No of  
Bolts** = 4

**Min Hole  
Size** = 2-1/4

**Bolt = 10  
Torque  
FT./LBS.**

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Bushing Dimension References

