

Part No: 469E-251SR

Schedule 40 White

Clamp-On Saddle

Desc: 2X1-1/2 PVC CLAMP SADDLE D/O SRFPT EPDM

MSRP: 71.67

Part Code: 046

Weight(lbs): 0.985

Weight(kg): 0.447

Weight(gm): 447

Size: 2"X1-1/2"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring EPDM

Hardware Zinc

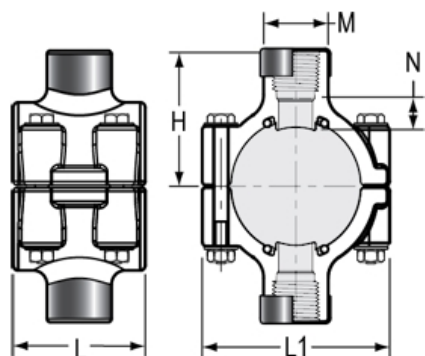

H = 2-15/16

L = 2-7/16

L1 = 3-7/16

M = 2-7/16

N = 13/16

No of Bolts = 4

Min Hole Size = 1-1/2

Bolt Torque = 8
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

