

Part No: 469E-626SR

Schedule 40 White

Clamp-On Saddle

Desc: 10X6 PVC CLAMP SADDLE D/O SRFPT EPDM ZNC

MSRP: 626.03

Part Code: 046

Weight(lbs): 16.493

Weight(kg): 7.481

Weight(gm): 7481

Size: 10"X6"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring EPDM

Hardware Zinc

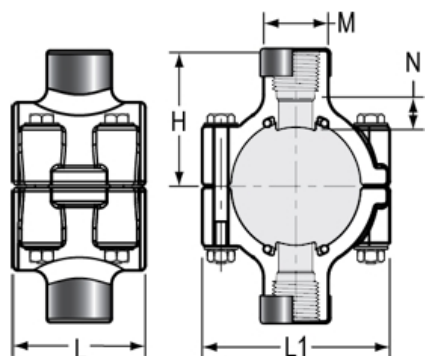

H = 9-7/32

L = 8-1/2

L1 = 12-1/4

M = 7-21/32

N = 2-5/16

No of Bolts = 6

Min Hole Size = 6

Bolt Torque = 10
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

