

Part No: 469S-421SR

Schedule 40 White

Clamp-On Saddle

Desc: 4X2-1/2 PVC CLAMP SADDLE D/O SRFPT BUNA

MSRP: 184

Part Code: 046

Weight(lbs): 4.081

Weight(kg): 1.851

Weight(gm): 1851

Size: 4"X2-1/2"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

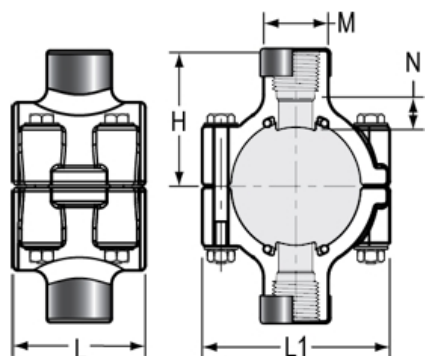

H = 5-5/32

L = 5-1/2

L1 = 5-13/16

M = 4-5/16

Bolt = 8
Torque
FT./LBS.

Min Hole = 3
Size

N = 1-5/16

No of = 4
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

