

Part No: 469S-529SR

Schedule 40 White

Clamp-On Saddle

Desc: 6X2-1/2 PVC CLAMP SADDLE D/O SRFPT BUNA

MSRP: 299.96

Part Code: 046

Weight(lbs): 5.955

Weight(kg): 2.701

Weight(gm): 2701

Size: 6"X2-1/2"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

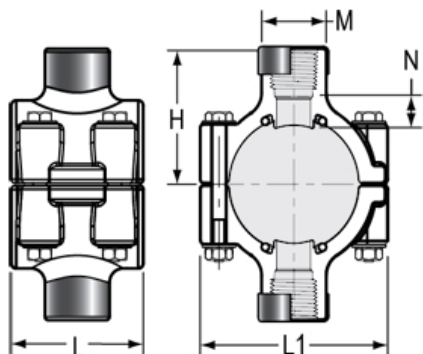

H = 6-9/32

L = 6

L1 = 8-3/16

Min Hole = 3
Size

Bolt = 10
Torque
FT./LBS.

M = 4-5/16

N = 1-13/32

No of = 4
Bolts

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Bushing Dimension References

