

**Part No:** 469S-576SR

**Schedule** 40 White

**Clamp-On Saddle**

**Desc:** 8X1-1/4 PVC CLAMP SADDLE D/O SRFPT BUNA

**MSRP:** 406.33

**Part Code:** 046

**Weight(lbs):** 8.741

**Weight(kg):** 3.965

**Weight(gm):** 3965

**Size:** 8"X1-1/4"


**Color:** WHITE

**Material:** PVC

**Connection** Double SR Fipt (Clamp-On)

**O-Ring** Buna-N

**Hardware** SS

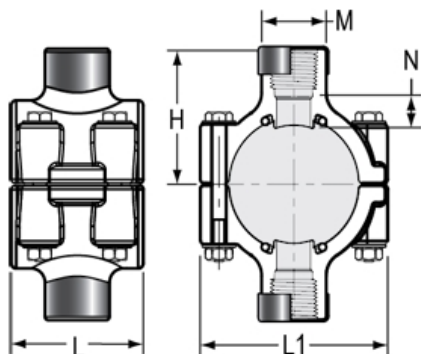

**H** = 6-3/4

**L** = 8- 1/2

**L1** = 10-1/16

**M** = 3-1/32

**N** = 1-7/16

**No of Bolts** = 6

**Bolt Torque** = 10  
FT./LBS.

**Min Hole Size** = 2-1/8

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Bushing Dimension References

