

Part No: 469S-577SR

Schedule 40 White

Clamp-On Saddle

Desc: 8X1-1/2 PVC CLAMP SADDLE D/O BUNA SRFPT

MSRP: 406.33

Part Code: 046

Weight(lbs): 8.662

Weight(kg): 3.929

Weight(gm): 3929

Size: 8"X1-1/2"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring Buna-N

Hardware SS

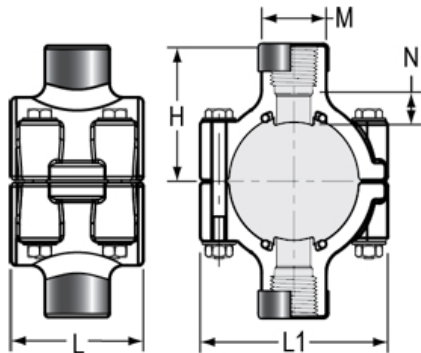

H = 6-3/4

L = 8- 1/2

L1 = 10-1/16

M = 3-1/32

N = 1-7/16

No of Bolts = 6

Min Hole Size = 2-1/8

Bolt Torque = 10
FT./LBS.

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Bushing Dimension References

