

Part No: 469SE-582SR

Schedule 40 White

Clamp-On Saddle

Desc: 8X4 PVC CLMP SADDLE D/O SR FPT EPDM SS B

MSRP: 500.36

Part Code: 046

Weight(lbs): 9.337

Weight(kg): 4.235

Weight(gm): 4235

Size: 8"X4"


Color: WHITE

Material: PVC

Connection Double SR Fipt (Clamp-On)

O-Ring EPDM

Hardware SS

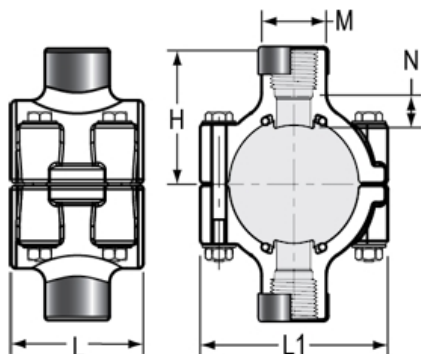

H = 7- 5/16

L = 8- 1/2

L1 = 10-1/16

M = 5- 1/4

N = 1-1/2

**No of
Bolts** = 6

**Min Hole
Size** = 4

**Bolt = 10
Torque
FT./LBS.**

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

