

**Part No:** 4721L1-005SR

**Valves**

**3-Way Ball Valve**

**Desc:** 1/2 PVC T/U IND 3WAY VERT L/I SRTHD EPDM

**MSRP:** 174.08

**Part Code:** 615

**Weight(lbs):** 0.54


**Weight(kg):** 0.245

**Weight(gm):** 245

**Size:** 1/2"

**Color:** GRAY

**Material:** PVC

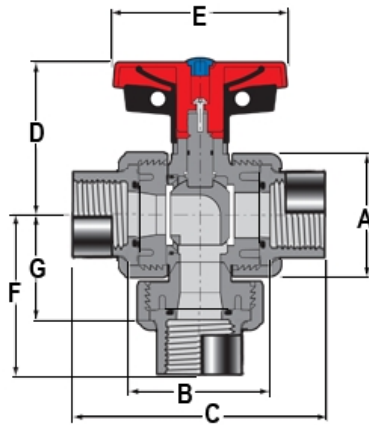

**A** = 1- 7/8

**B** = 2- 7/16

**C** = 3-13/16

**D** = 2- 9/16

**E** = 2-13/16

**F** = 2- 3/8

**G** = 1-11/16

**Type** Single L - Port (Vertical)

**Connection** SR Fipt

**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

