

Part No: 4721L1-007CSR

Valves

3-Way Ball Valve

Desc: 3/4 CPVC T/U IND 3WAY VRT L/1 SRTHD EPDM

MSRP: 320.01

Part Code: 617

Weight(lbs): 0.851


Weight(kg): 0.386

Weight(gm): 386

Size: 3/4"

Color: GRAY

Material: CPVC

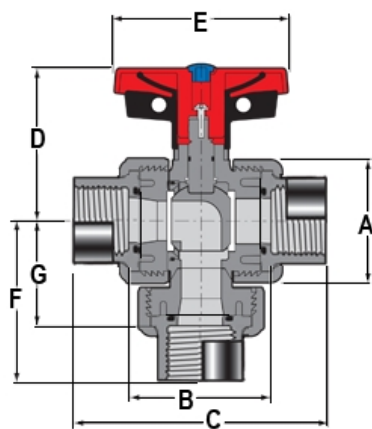

A = 2- 1/4

B = 2- 3/4

C = 4- 1/4

D = 2- 7/8

E = 3- 5/16

F = 2- 3/4

G = 2

Type Single L - Port (Vertical)
Connection SR Fipt
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

