

Part No: 4721L1-010CSR

Valves

3-Way Ball Valve

Desc: 1 CPVC T/U IND 3WAY VERT L/1 SR/THD EPDM

MSRP: 386.38

Part Code: 617

Weight(lbs): 1.162


Weight(kg): 0.527

Weight(gm): 527

Size: 1"

Color: GRAY

Material: CPVC

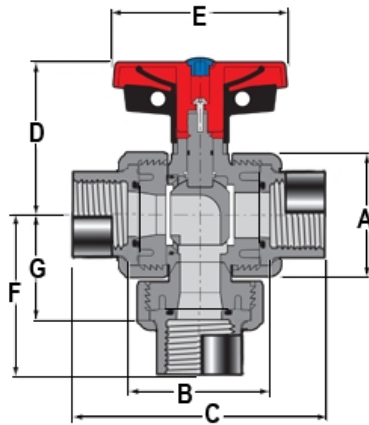

A = 2- 9/16

B = 2- 7/8

C = 4-11/16

D = 3- 1/8

E = 3- 7/16

F = 3

G = 2- 1/8

Type Single L - Port (Vertical)
Connection SR Fipt
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

