

**Part No:** 4721L2-010CSR

**Valves**

**3-Way Ball Valve**

**Desc:** 1 CPVC T/U IND 3WAY VERT L/2 SR/THD EPDM

**MSRP:** 647.88

**Part Code:** 617

**Weight(lbs):** 1.153


**Weight(kg):** 0.523

**Weight(gm):** 523

**Size:** 1"

**Color:** GRAY

**Material:** CPVC

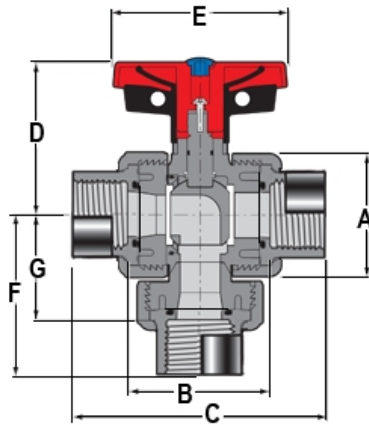

**A** = 2- 9/16

**B** = 2- 7/8

**C** = 4-11/16

**D** = 3- 1/8

**E** = 3- 7/16

**F** = 3

**G** = 2- 1/8

**Type** Double L - Port (Vertical)  
**Connection** SR Fipt  
**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

