

Part No: 4721L3-020CSR

Valves

3-Way Ball Valve

Desc: 2 CPVC T/U IND 3WAY VERT L/3 SR/THD EPDM

MSRP: 942.88

Part Code: 617

Weight(lbs): 3.644


Weight(kg): 1.653

Weight(gm): 1653

Size: 2"

Color: GRAY

Material: CPVC

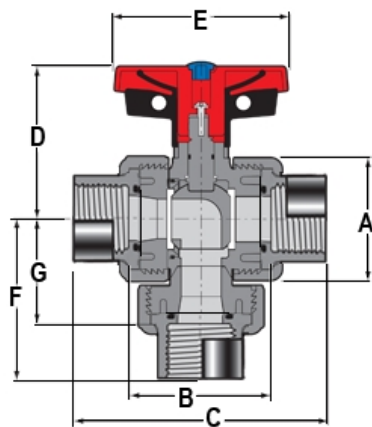

A = 4- 1/4

B = 4- 3/4

C = 6- 3/4

D = 4- 1/2

E = 5- 1/8

F = 4- 1/2

G = 3- 1/2

Type Triple L - Port (Vertical)

Connection SR Fipt

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

