

**Part No:** 4721L3-025CSR

**Valves**

**3-Way Ball Valve**

**Desc:** 2-1/2 CPVC T/U IND 3WY VRT L3 SRTHD EPDM

**MSRP:** 2593.26

**Part Code:** 617

**Weight(lbs):** 10.064


**Weight(kg):** 4.565

**Weight(gm):** 4565

**Size:** 2-1/2"

**Color:** GRAY

**Material:** CPVC

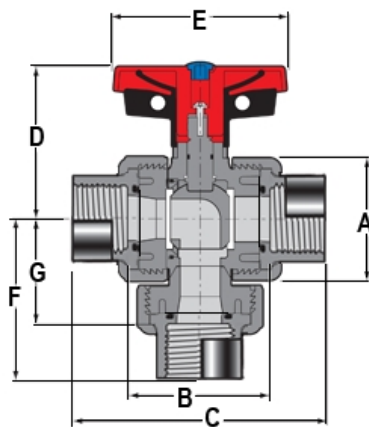

**A** = 6-3/16

**B** = 7-1/8

**C** = 9-7/8

**D** = 5-7/8

**E** = 7-5/8

**F** = 6-1/4

**G** = 4-7/8

**Type** Triple L - Port (Vertical)  
**Connection** SR Fipt  
**O-Ring** EPDM

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

