

Part No: 4721L3-025SR

Valves

3-Way Ball Valve

Desc: 2-1/2 PVC T/U IND 3WY VERT L3 SRTHD EPDM

MSRP: 1705.38

Part Code: 615

Weight(lbs): 9.544


Weight(kg): 4.329

Weight(gm): 4329

Size: 2-1/2"

Color: GRAY

Material: PVC

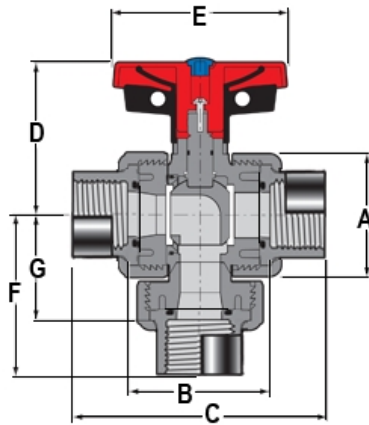

A = 6-3/16

B = 7-1/8

C = 9-7/8

D = 5-7/8

E = 7-5/8

F = 6-1/4

G = 4-7/8

Type Triple L - Port (Vertical)
Connection SR Fipt
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

