

Part No: 4721T1-007SR

Valves

3-Way Ball Valve

Desc: 3/4 PVC T/U IND 3WY VERT T/PT SRT HD EPDM

MSRP: 207.89

Part Code: 615

Weight(lbs): 0.831


Weight(kg): 0.377

Weight(gm): 377

Size: 3/4"

Color: GRAY

Material: PVC

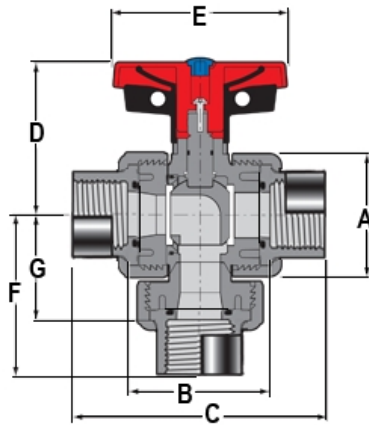

A = 2- 1/4

B = 2- 3/4

C = 4- 1/4

D = 2- 7/8

E = 3- 5/16

F = 2- 3/4

G = 2

Type T - Port (Vertical)

Connection SR Fipt

O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

