

Part No: 4722L1-025C

Valves

3-Way Ball Valve

Desc: 2-1/2 CPVC T/U IND 3WY VERT L/1 SOC EPDM

MSRP: 2268.37

Part Code: 617

Weight(lbs): 9.943


Weight(kg): 4.51

Weight(gm): 4510

Size: 2-1/2"

Color: GRAY

Material: CPVC

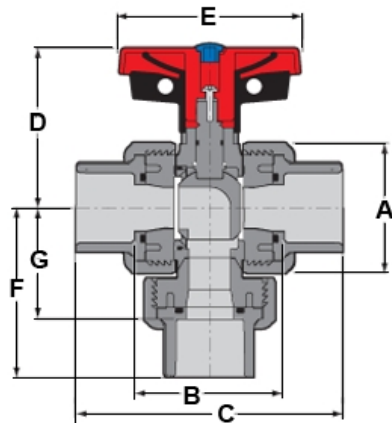

A = 6-3/16

B = 7-1/8

C = 10-5/8

D = 5-7/8

E = 7-5/8

F = 6-5/8

G = 4-7/8

Type Single L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

