

Part No: 4722L2-012

Valves

3-Way Ball Valve

Desc: 1-1/4 PVC T/U IND 3WAY VERT L/2 SOC EPDM

MSRP: 465.49

Part Code: 615

Weight(lbs): 1.667


Weight(kg): 0.756

Weight(gm): 756

Size: 1-1/4"

Color: GRAY

Material: PVC

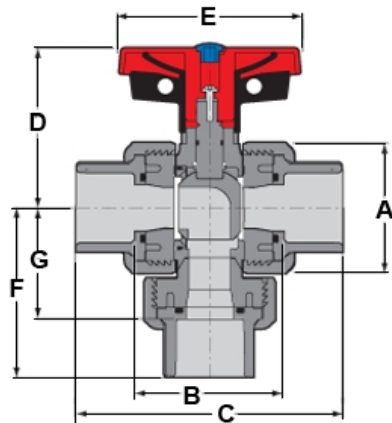

A = 3-3/16

B = 3-5/16

C = 5-13/16

D = 3- 5/8

E = 3-7/8

F = 3- 3/4

G = 2-1/2

Type Double L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

