

Part No: 4722L2-030

Valves

3-Way Ball Valve

Desc: 3 PVC T/U IND 3WAY VERT L/2 SOC EPDM

MSRP: 1674.57

Part Code: 615

Weight(lbs): 9.581


Weight(kg): 4.346

Weight(gm): 4346

Size: 3"

Color: GRAY

Material: PVC

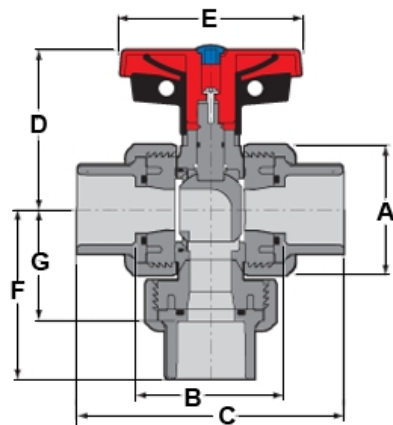

F = 6-3/4 **G** = 4- 7/8

A = 6- 3/16

B = 7

C = 10-3/4

D = 5- 7/8

E = 7- 5/8

Type Double L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

