

Part No: 4722L2-040C

Valves

3-Way Ball Valve

Desc: 4 CPVC T/U IND 3WAY VERT L/2 SOC EPDM

MSRP: 4262.57

Part Code: 617

Weight(lbs): 16.826


Weight(kg): 7.632

Weight(gm): 7632

Size: 4"

Color: GRAY

Material: CPVC

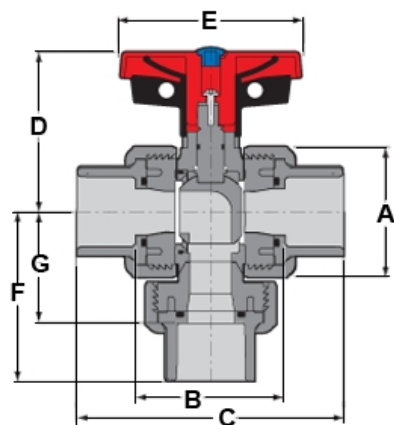

A = 7-3/4

B = 7-7/16

C = 11-15/16

D = 6-11/16

E = 9

F = 8-3/16

G = 5-15/16

Type Double L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

