

Part No: 4722L3-007C

Valves

3-Way Ball Valve

Desc: 3/4 CPVC T/U IND 3WAY VERT L/3 SOC EPDM

MSRP: 570.79

Part Code: 617

Weight(lbs): 0.84


Weight(kg): 0.381

Weight(gm): 381

Size: 3/4"

Color: GRAY

Material: CPVC

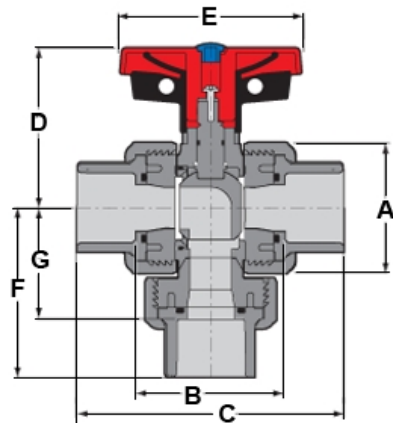

A = 2-3/8

B = 2-3/4

C = 4-3/4

D = 2-7/8

E = 3-3/8

F = 3-1/16

G = 2-1/16

Type Triple L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

