

Part No: 4722L3-040

Valves

3-Way Ball Valve

Desc: 4 PVC T/U IND 3WAY VERT L/3 SOC EPDM

MSRP: 2770.8

Part Code: 615

Weight(lbs): 17.705


Weight(kg): 8.031

Weight(gm): 8031

Size: 4"

Color: GRAY

Material: PVC

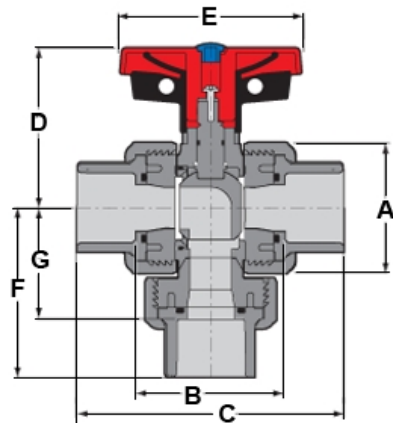

A = 7-3/4

B = 7-7/16

C = 11-15/16

D = 6-11/16

E = 9

F = 8-3/16

G = 5-15/16

Type Triple L - Port (Vertical)
Connection Socket
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

