

Part No: 4723L1-005C

Valves

3-Way Ball Valve

Desc: 1/2 CPVC T/U IND 3WAY VERT L/1 FLG EPDM

MSRP: 544.59

Part Code: 617

Weight(lbs): 1.177


Weight(kg): 0.534

Weight(gm): 534

Size: 1/2

Color: GRAY

Material: CPVC

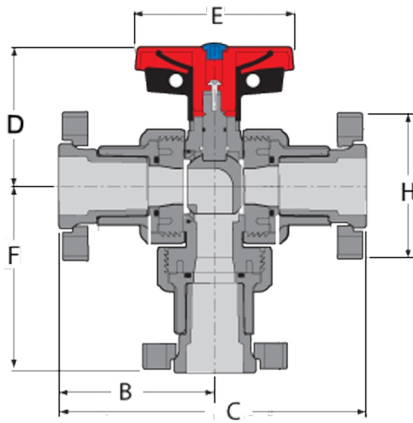

B = 2- 7/16

C = 4- 3/16

D = 2- 9/16

E = 2-13/16

F = 4-11/32

H = 3-1/2

Type Single L - Port (Vertical)
Connection Flanged
O-Ring EPDM

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

